


Branching module FRM-Y-D-MAXI

Part number: 542186

FESTO

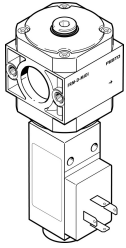

Data sheet

| Feature | Value |
|--|--|
| Mounting position | optional |
| Design | Branching module |
| Operating pressure | 0 bar...12 bar |
| Standard nominal flow rate in main flow direction 1->2 | 20000 l/min |
| Operational voltage range DC | 0 V...125 V |
| Operating medium | Compressed air to ISO 8573-1:2010 [7:-:-] Inert gases |
| Corrosion resistance class CRC | 2 - Moderate corrosion stress |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |
| Storage temperature | -10 °C...60 °C |
| Air purity class at output | Compressed air to ISO 8573-1:2010 [7:-:-] Inert gases |
| Media temperature | -10 °C...60 °C |
| Ambient temperature | -10 °C...60 °C |
| Product weight | 822 g |
| Pneumatic connection, port 3 | G3/4 |
| Pneumatic connection, port 4 | G1/4 |
| Note on materials | RoHS-compliant |
| Material housing | Die-cast aluminium |