


Axial kit EAMM-A-D32-40A

Part number: 543147

FESTO

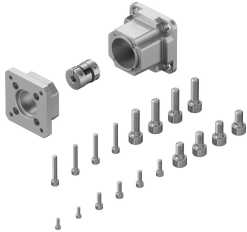

Data sheet

Feature	Value
Mounting position	optional
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C...60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C...60 °C
Transmittable torque	1.6 Nm
Product weight	130 g
Interface code, actuator	D32A D32B
Interface code, motor in	40A
Note on materials	RoHS-compliant