


Parallel kit EAMM-U-D32-32B

Part number: 543152

FESTO

Suitable for electric drives.

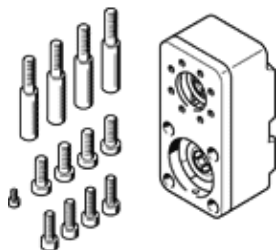

Data sheet

Feature	Value
Size	32
Assembly position	Any
Max. speed	6,000 1/min
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Protection class	IP40
Ambient temperature	0 ... 50 °C
Mass moment of inertia	2.931 kgmm ²
No-load driving torque	0.05 Nm
Transferable torque	1 Nm
Product weight	300 g
Materials note	Contains PWIS substances