


parallel kit EAMM-U-D40-55A

Part number: 543157

FESTO

Suitable for electric drives.

Type to be discontinued. Available until 2023. See Support Portal for alternative products.

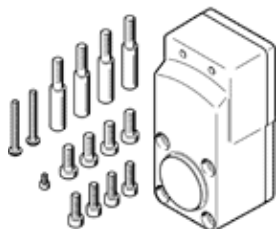

Data sheet

| Feature | Value |
|------------------------|--------------------------|
| Size | 40 |
| Assembly position | Any |
| Max. speed | 5,000 1/min |
| PWIS conformity | VDMA24364 zone III |
| Storage temperature | -25 ... 60 °C |
| Relative air humidity | 0 - 95 % |
| Protection class | IP40 |
| Ambient temperature | 0 ... 50 °C |
| Mass moment of inertia | 10.016 kgmm ² |
| No-load driving torque | 0.1 Nm |
| Transferable torque | 3 Nm |
| Product weight | 530 g |