


multi-pin node VABE-S6-1LT-C-M1-S37

Part number: 543414

FESTO

For valve terminals VTSA and VTSA-F.

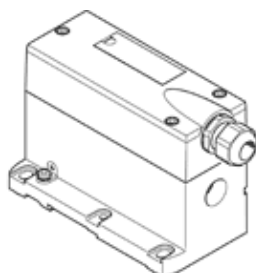

Data sheet

Feature	Value
Assembly position	Any
Max. number of valve positions	16 with bistable valves 32 with monostable valves
Nominal operating voltage DC	24 V
Permissible voltage fluctuation	+/- 10 %
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Protection class	IP65 NEMA 4
Ambient temperature	-5 ... 50 °C
Product weight	459 g
Electrical connection	Multi-pin plug Cable with plug
Material cover	PA
Material housing	Aluminium die cast