


Sub-base VMPA2-IC-AP-S-1-EX2

Part number: 545450

FESTO

For valve terminal MPA-S.

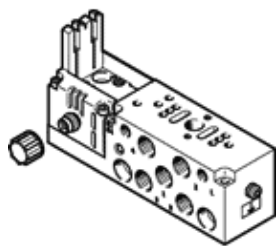

Data sheet

Feature	Value
Width	30.5 mm
Length	107.3 mm
Grid dimension	21 mm
Operating pressure	3 ... 8 bar
Pilot pressure	3 ... 8 bar
ATEX category Gas	II 3G
Explosion ignition protection type Gas	Ex nA II T4 X
ATEX category Dust	II 3D
Explosion ignition protection type Dust	Ex tD A22 IP54 T95°C X
Explosion-proof ambient temperature	-5 °C ≤ Ta ≤ +50 °C
Corrosion resistance classification CRC	0
Ambient temperature	-5 ... 50 °C
Electrical connection	Plug M8
Mounting method for sub-base	with through hole
Pilot exhaust port 82/84	M5
Pneumatic connection, port 1	G1/8
Pneumatic connection, port 2	G1/8
Pneumatic connection, port 3	G1/8
Pneumatic connection, port 4	G1/8
Pneumatic connection, port 5	G1/8
Materials note	Conforms to RoHS
Materials information for sub-base	Aluminium die cast