

 

pushbutton actuator T-3-M5-BK

Part number: 546055
Product to be discontinued

FESTO

This type is suitable for vacuum.

Type to be discontinued. Available until 2018. See Support Portal for alternative products.

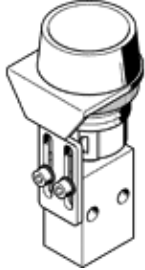

Data sheet

Feature	Value
Valve function	3/2 closed, monostable
Type of actuation	manual
Width	22.5 mm
Standard nominal flow rate	80 l/min
Operating pressure	-0.95 ... 8 bar
Design structure	Piston seat
Type of reset	mechanical spring
Nominal size	2 mm
Assembly position	Any
Type of piloting	direct
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Corrosion resistance classification CRC	1 - Low corrosion stress
Medium temperature	-10 ... 60 °C
Ambient temperature	-10 ... 60 °C
Actuating force	14 N
Product weight	416 g
Mounting type	with through hole
Pneumatic connection, port 1	M5
Pneumatic connection, port 2	M5
Materials information for seals	NBR
Materials information, housing	Wrought Aluminium alloy Anodised