


quick coupling plug KS-PK-6-1/8

Part number: 546075
Product to be discontinued

FESTO

Type to be discontinued. Available until 2023. See Support Portal for alternative products.

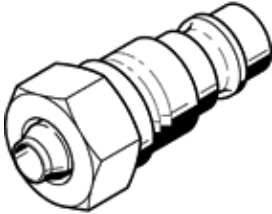

Data sheet

| Feature | Value |
|---|---|
| Nominal size | 5 mm |
| Operating pressure | -0.95 ... 12 bar |
| Standard nominal flow rate | 630 l/min |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [7:-:-] |
| Note on operating and pilot medium | Lubricated operation possible (subsequently required for further operation) |
| Corrosion resistance classification CRC | 1 - Low corrosion stress |
| PWIS conformity | VDMA24364-B1/B2-L |
| Ambient temperature | -10 ... 60 °C |
| Product weight | 18 g |
| Pneumatic connection | PK-6 |