


# adapter AD-3/4NPT-G3/4-I

Part number: 546551

FESTO

Female thread one side, male thread on the other.

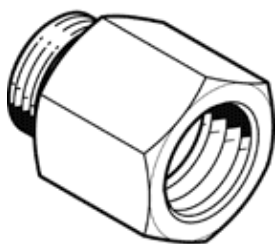

## Data sheet

Feature	Value
Nominal size	19.05 mm
Operating pressure complete temperature range	-0.95 ... 10 bar
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 ... 60 °C
Max. tightening torque, pneumatic connection 1	32 Nm
Max. tightening torque, pneumatic connection 2	60 Nm
Product weight	98.13 g
Pneumatic connection, port 1	Male thread, 3/4 NPT
Pneumatic connection, port 2	Female thread G3/4
Materials note	Conforms to RoHS
Material seals	PVC
Material housing	steel, galvanized