


# Distributor FR-8-1/8-BR

Part number: 546749

FESTO

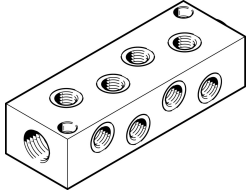

## Data sheet

Feature	Value
Nominal size	8.6 mm
Mounting position	optional
Operating pressure complete temperature range	0 bar...16 bar
Operating medium	Compressed air to ISO 8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (in which case lubricated operation will always be required)
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Number of outputs	8
Number of supply lines	1
Pneumatic connection, port 1	G3/8
Pneumatic connection, port 2	G1/8
Material housing	Wrought aluminium alloy