


## sub-base VMPAF-AP-4-1-EMM-4

Part number: 547496  
Product to be discontinued

FESTO

Type to be discontinued. Available until 2019. See Support Portal for alternative products.

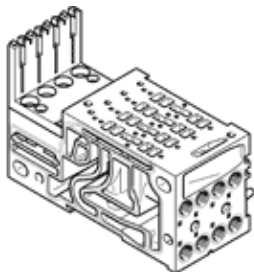

### Data sheet

Feature	Value
Width	47.6 mm
Length	107.3 mm
Grid dimension	10.5 mm
Max. number of valve positions	4
Operating pressure	-0.9 ... 10 bar
Pilot pressure	3 ... 8 bar
Corrosion resistance classification CRC	0 - No corrosion stress
Ambient temperature	-5 ... 50 °C
Pneumatic connection, port 2	M7
Pneumatic connection, port 4	M7
Materials note	Conforms to RoHS
Material of connecting plate	Aluminium die cast