


sub-base VMPAF-AP-2-1-EMM-2

Part number: 547497
Product to be discontinued

FESTO

Type to be discontinued. Available until 2019. See Support Portal for alternative products.

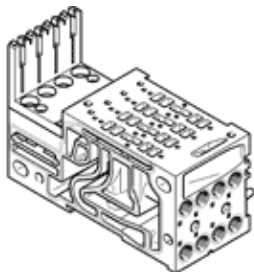

Data sheet

Feature	Value
Width	47.6 mm
Length	107.3 mm
Grid dimension	10.5 mm
Max. number of valve positions	2
Operating pressure	-0.9 ... 10 bar
Pilot pressure	3 ... 8 bar
Corrosion resistance classification CRC	0 - No corrosion stress
Ambient temperature	-5 ... 50 °C
Pneumatic connection, port 2	G1/4
Pneumatic connection, port 4	G1/4
Materials note	Conforms to RoHS
Material of connecting plate	Aluminium die cast