


sub-base VMPAF-AP-2-2-T0

Part number: 547505
Product to be discontinued

FESTO

Type to be discontinued. Available until 2019. See Support Portal for alternative products.

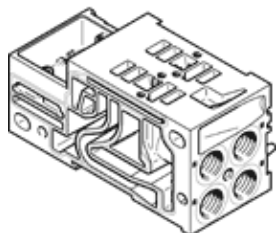

Data sheet

| Feature | Value |
|---|-------------------------|
| Width | 47.6 mm |
| Length | 107.3 mm |
| Grid dimension | 10.5 mm |
| Max. number of valve positions | 2 |
| Operating pressure | -0.9 ... 10 bar |
| Pilot pressure | 3 ... 8 bar |
| Corrosion resistance classification CRC | 0 - No corrosion stress |
| Ambient temperature | -5 ... 50 °C |
| Pneumatic connection, port 2 | G1/4 |
| Pneumatic connection, port 4 | G1/4 |
| Materials note | Conforms to RoHS |
| Material of connecting plate | Aluminium die cast |