

# T-fitting


## NPFB-T-2G34-R34-FMF

Part number: 547763

FESTO

For connection with pipes.

When using R and G threaded lugs, thread sealing tape or liquid sealant is recommended as an additional sealing material. For sealing the G threaded lug, an axial sealing ring of soft aluminium AL 99.5 can also be used.

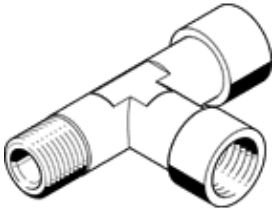

## Data sheet

Feature	Value
Material information for threaded fitting	Brass Nickel plated
Container size	10
Operating pressure	-0.95 ... 40 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [-:::]
Corrosion resistance classification CRC	1
Ambient temperature	-20 ... 150 °C
Product weight	172 g
Pneumatic connection, port 1	G3/4
Pneumatic connection, port 2	R3/4
Materials note	Conforms to RoHS