


# solenoid coil

## MD-2-110VAC-PA

Part number: 549904

FESTO

For AC voltage, without plug socket.

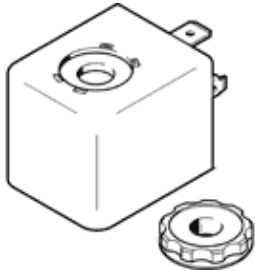

## Data sheet

Feature	Value
Type of actuation	electrical
Assembly position	Any
Duty cycle	100 %
Power factor cos {phi}	0.7
Characteristic coil data	110 V AC: 50/60 Hz, pick-up power 14.5 VA, holding power 10.5 VA
Permissible frequency fluctuation	+/- 10 %
Permissible voltage fluctuation	+/- 10 %
CE mark (see declaration of conformity)	to EU directive low-voltage devices
UKCA marking (see declaration of conformity)	To UK instructions for electrical equipment
PWIS conformity	VDMA24364-B2-L
Protection class	IP65
Ambient temperature	-20 ... 50 °C
Max. tightening torque for fitting	0.5 Nm
Product weight	110 g
Electrical connection	Per DIN EN 175301-803
Mounting type	With knurled nut
Materials note	Conforms to RoHS
Material solenoid coil	Duroplast Copper Steel
Material winding	Copper