


solenoid coil

MD-2-230VAC-PA

Part number: 549905

FESTO

For AC voltage, without plug socket.

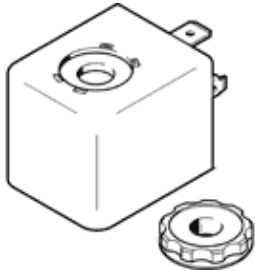

Data sheet

| Feature | Value |
|--|--|
| Type of actuation | electrical |
| Assembly position | Any |
| Duty cycle | 100 % |
| Power factor cos {phi} | 0.7 |
| Characteristic coil data | 230 V AC: 50/60 Hz, pick-up power 14.5 VA, holding power 10.5 VA |
| Permissible frequency fluctuation | +/- 10 % |
| Permissible voltage fluctuation | +/- 10 % |
| CE mark (see declaration of conformity) | to EU directive low-voltage devices |
| UKCA marking (see declaration of conformity) | To UK instructions for electrical equipment |
| PWIS conformity | VDMA24364-B2-L |
| Protection class | IP65 |
| Ambient temperature | -20 ... 50 °C |
| Max. tightening torque for fitting | 0.5 Nm |
| Product weight | 110 g |
| Electrical connection | Per DIN EN 175301-803 |
| Mounting type | With knurled nut |
| Materials note | Conforms to RoHS |
| Material solenoid coil | Duroplast Copper Steel |
| Material winding | Copper |