 



Silencer UOS-1

Part number: 552252

FESTO

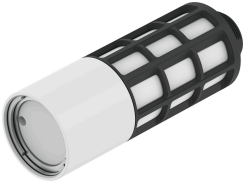

Data sheet

Feature	Value
Type of seal on screwed plug	No seal
Mounting position	optional
Design	Open silencer
Operating pressure	0 MPa...1 MPa 0 bar...10 bar
Operating medium	Compressed air to ISO 8573-1:2010 [-:~:]
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Sound pressure level	75 dB(A)
Ambient temperature	-10 °C...50 °C
Type of mounting	Via male thread
Product weight	200 g
Pneumatic connection	G1
Material shock absorber insert	PE
Note on materials	RoHS-compliant
Material housing	POM
Material sleeve	Wrought aluminium alloy