


**coupling**  
**EAMC-30-35-10-12**  
Part number: 552640

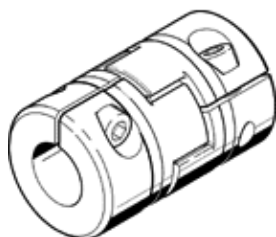

**Data sheet**

Feature	Value
Holder diameter 1	10 mm
Holder diameter 2	12 mm
Size	30
Nominal length	35 mm
Assembly position	Any
Max. speed	8,000 1/min
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-25 ... 60 °C
Mass moment of inertia	6.1 kgmm <sup>2</sup>
Transferable torque	8.8 Nm
Product weight	45 g
Materials note	Conforms to RoHS