


# Vacuum filter VAF-DB-3/8

Part number: 553140

FESTO

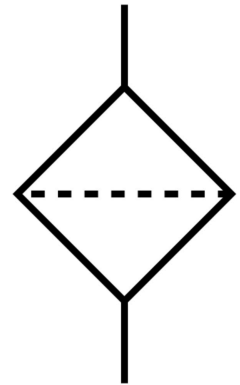

## Data sheet

| Feature                    | Value  |
|----------------------------|--|
| Mounting position          | Vertical   |
| Grade of filtration        | 80 µm  |
| Operating pressure         | -0.95 bar...0 bar                                |
| Note on operating pressure | Only for use in open vacuum systems              |
| Operating medium           | Compressed air to ISO 8573-1:2010 [7::-]         |
| LABS (PWIS) conformity     | VDMA24364 zone III                               |
| Ambient temperature        | -5 °C...50 °C                                    |
| Max. tightening torque     | 15.3 Nm  |
| Product weight             | 156 g  |
| Type of mounting           | In-line installation<br>Via wall/surface bracket |
| Pneumatic connection       | G3/8   |
| Vacuum connection          | G3/8   |
| Note on materials          | RoHS-compliant                                   |
| Material seals             | NBR  |
| Material filter            | PE   |
| Material housing           | PP reinforced                                    |
| Material bowl              | PA   |
| Suitable for ejector pulse | 7 bar  |