


plastic tubing PLN

Part number: 553850

FESTO

Please observe the minimum order quantity.

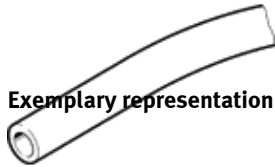

Data sheet

Overall data sheet – Individual values depend upon your configuration.

Feature	Value
Outside diameter	4 ... 16 mm
Inside diameter	2.9 ... 12 mm
Temperature dependent operating pressure	-0.95 ... 14 bar
Authorisation	TÜV
Certificate issuing department	B 013277 0506 00
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-] Water as per manufacturer's declaration at www.festo.com
PWIS conformity	VDMA24364-B1/B2-L
Cleanroom class	This product is a static object, active particle generation is not possible when used correctly. Clean product before using it in a cleanroom environment and ensure it is installed correctly.
Food-safe	See Supplementary material information
Ambient temperature	-30 ... 80 °C
Colour	blue brown yellow green neutral Red Black silver white
Materials note	Conforms to RoHS
Material tubing	PE