


# electrical interface

## CECX-S-S4

Part number: 553979

FESTO

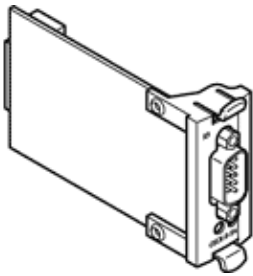

## Data sheet

Feature	Value
Corrosion resistance classification CRC	0 - No corrosion stress
Authorisation	c UL us - Listed (OL)
Materials note	Contains PWIS substances Conforms to RoHS
Ambient temperature	5 ... 55 °C
Storage temperature	-40 ... 70 °C
Relative air humidity	10 - 95 %
Protection class	IP20
Safety class	III
Product weight	31 g
Test for insensitivity to vibration	EN 60068-2-6 FC 5 - 9 Hz 3,5 mm 9 - 150 Hz 1g
Test for insensitivity to shock	EN 60068-2-27 EA 15 g, 11 ms (half sine)
Serial interface, number	1
Serial interface, type	RS 485-A/422-A
Serial interface, connection technology	Plug Sub-D 9-pin
Serial interface, transmission rate	1200 ... 115000 Bit/s Adjustable via software
Serial interface, electrical isolation	No