


90° connection plate VABF-S2-2-A1G2-N12

Part number: 555703

FESTO

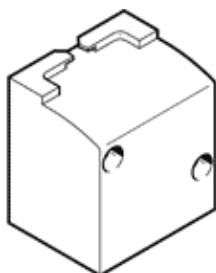

Data sheet

| Feature | Value |
|---|---|
| Width | 58.1 mm |
| Based on the standard | ISO 5599-2 |
| Assembly position | Any |
| Operating pressure MPa | -0.09 ... 1 MPa |
| Operating pressure | -0.9 ... 10 bar |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [7:4:4] |
| Note on operating and pilot medium | Lubricated operation possible (subsequently required for further operation) |
| Corrosion resistance classification CRC | 0 - No corrosion stress |
| PWIS conformity | VDMA24364-B1/B2-L |
| Protection class | IP65 NEMA 4 |
| Ambient temperature | -5 ... 50 °C |
| Product weight | 359 g |
| Mounting type | with through hole |
| Materials note | Conforms to RoHS |
| Material housing | Wrought Aluminium alloy |