


Coupling EAMC-30-35-8-9

Part number: 558903

FESTO

Suitable for cantilever axis EGSA.

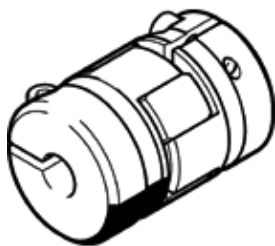

Data sheet

Feature	Value
Holder diameter 1	8 mm
Holder diameter 2	9 mm
Size	30
Assembly position	Any
Max. speed	12,000 1/min
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-25 ... 60 °C
Mass moment of inertia	6.06 kgmm ²
Transferable torque	5.1 Nm
Product weight	45 g
Materials note	Conforms to RoHS