


# connecting cable

## VMPAL-KMSK-S-SD25-IP67-2.5

Part number: 560413

FESTO

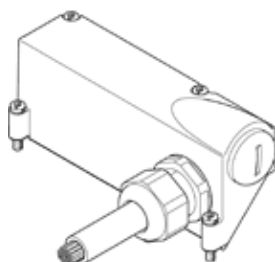

### Data sheet

Feature	Value
Product weight	610 g
Electrical connection	Cable with plug
Cable length	2.5 m
Cable attribute	Suitable for energy chains
Min. cable bending radius	63 mm
Cable diameter	12.5 mm
Cable structure	25x0,34
Protection class	IP67 to IEC 60529
Ambient temperature with flexible cable installation	-5 ... 80 °C
CE mark (see declaration of conformity)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B1/B2-L
Materials note	Conforms to RoHS
Corrosion resistance classification CRC	2 - Moderate corrosion stress
Material cable sheath	TPE-U(PU)