


manifold sub-base VABV-S2-2S-G12-T2

Part number: 560841

FESTO

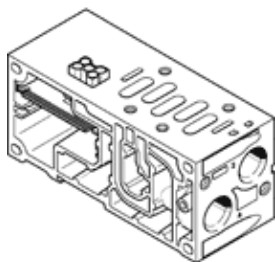

Data sheet

| Feature | Value |
|--|---|
| Grid dimension | 59 mm |
| Valve terminal type | 44 |
| Operating pressure MPa | -0.09 ... 1 MPa |
| Operating pressure | -0.9 ... 10 bar |
| CE mark (see declaration of conformity) | to EU directive low-voltage devices |
| UKCA marking (see declaration of conformity) | To UK instructions for electrical equipment |
| Corrosion resistance classification CRC | 0 - No corrosion stress |
| PWIS conformity | VDMA24364-B1/B2-L |
| Product weight | 610 g |
| Pneumatic connection, port 2 | G1/2 |
| Pneumatic connection, port 4 | G1/2 |
| Materials note | Conforms to RoHS |
| Material plate | Aluminium die cast |