 



push-in T-connector NEDU-M12D4-M12T4-IS

Part number: 562248

FESTO

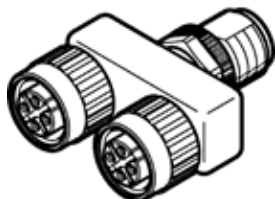

Data sheet

Feature	Value
Based on the standard	EN 61076-2-101
Connection frequency	100
Mounting type	Threaded
Product weight	25.5 g
Electrical connection	4-pin/4-pin/4-pin A-coded/A-coded/A-coded Socket/socket/plug M12x1 / M12x1 / M12x1
Operating voltage range DC	0 ... 30 V
Protection class	IP65 IP67
Ambient temperature	-25 ... 85 °C
PWIS conformity	VDMA24364-B2-L
Materials note	Conforms to RoHS
Corrosion resistance classification CRC	3 - High corrosion stress
Material housing	TPE-U (PU), amplified Zinc die-casting
Material of union nut	PA-reinforced
Material seals	FPM
Material electrical contact	Copper alloy Gold plated