


Axial kit EAMM-A-P6-38A-57A

Part number: 562645

FESTO

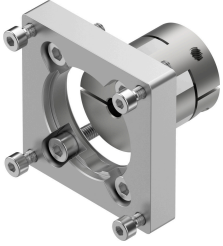

Data sheet

Feature	Value
Mounting position	optional
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C...60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C...60 °C
Transmittable torque	6.5 Nm
Product weight	130 g
Interface code, actuator	P6-38A
Interface code, motor in	57A
Interface code, clutch housing	38A
Note on materials	RoHS-compliant