


axial kit EAMM-A-P6-38A-40A

Part number: 562646

FESTO

Suitable for electric drives.

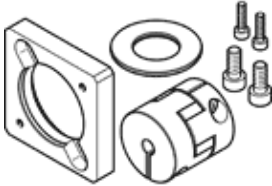

Data sheet

| Feature | Value |
|----------------------------------|------------------|
| Assembly position | Any |
| PWIS conformity | VDMA24364-B2-L |
| Storage temperature | -25 ... 60 °C |
| Relative air humidity | 0 - 95 % |
| Protection class | IP40 |
| Ambient temperature | -10 ... 60 °C |
| Transferable torque | 6.5 Nm |
| Product weight | 100 g |
| Interface code, actuator | P6-38A |
| Interface code, motor in | 40A |
| Interface code, coupling housing | 38A.2 |
| Materials note | Conforms to RoHS |