


solenoid coil

VACC-S13-18-A1-3U

Part number: 562892

FESTO

for armature system F19, connection pattern type A, to EN 175 301, 230 V DC and AC.

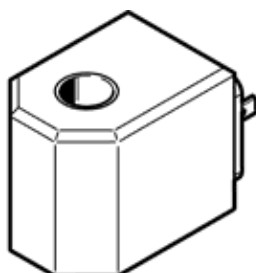

Data sheet

| Feature | Value |
|--|--|
| Type of actuation | electrical |
| Assembly position | Any |
| Switching position indicator | No |
| Duty cycle | 100 % |
| Insulation class | H |
| Characteristic coil data | 230 V DC: 1.8 W 230 V AC: 50/60 Hz, power: 1.8 VA |
| Permissible voltage fluctuation | -15 % / +10 % |
| CE mark (see declaration of conformity) | to EU directive low-voltage devices |
| UKCA marking (see declaration of conformity) | To UK instructions for electrical equipment |
| Corrosion resistance classification CRC | 4 - Very high corrosion stress |
| PWIS conformity | VDMA24364 zone III |
| Protection class | IP65 |
| Ambient temperature | -20 ... 60 °C |
| Product weight | 210 g |
| Electrical connection | Plug pattern type A to EN 175301-803 Plug to EN 175301-803 |
| Materials note | Conforms to RoHS |
| Material solenoid coil | PA UP |