


cable

NEBC-S1G15-K-2.5-N-B-S1G9-V

Part number: 563782

FESTO

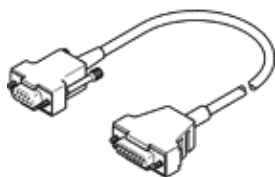

Data sheet

Feature	Value
Assembly position	Any
Electrical connection	Straight socket / straight socket Sub-D / Sub-D 15-pin / 9-pin
Cable length	2.5 m
Cable attribute	Standard
Min. cable bending radius	79 mm
Cable diameter	6.6 mm
Cable type	LIYCY
Cable structure	6x0,34 Shielded
Colour code, core insulation	DIN 47100
Protection class	IP40
Ambient temperature	-30 ... 80 °C
Ambient temperature with flexible cable installation	-5 ... 70 °C
Materials note	Conforms to RoHS
Corrosion resistance classification CRC	0 - No corrosion stress
Material cable sheath	PVC
Cable sheath colour	Grey
Material housing	Plastic, metallised Metal
Material electrical contact	Gold plated