


electrical connection box

VAVE-L1-1VH2-LP

Part number: 566714

★ Core product range

FESTO

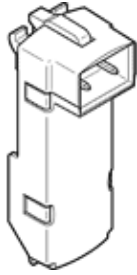

Data sheet

Feature	Value
Polarity protected	Bipolar
Additional functions	Spark arresting
Signal status display	LED
Nominal operating voltage DC	24 V 12 V
Surge strength	0.8 kV
Degree of contamination	3
Extended ambient temperature	-5 - 60 °C
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Protection class	IP40
Ambient temperature	-5 ... 50 °C
Assembly position	Any
Product weight	1.5 g
Electrical connection	2-pin Plug socket
Protective earth connection	Not available
Mounting type	Clip
Housing colour	Black
Materials note	Conforms to RoHS
Material housing	PA