

Plastic tubing


PUN-H-3/8-SI-500-HA

Part number: 568012

FESTO

Approved for use in food processing (hydrolysis resistant)

This product is only available if ordered from the Festo Corporation, USA.

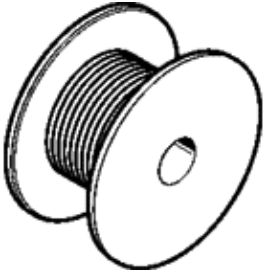

Data sheet

Feature	Value
Outer diameter, inches	3/8
Bending radius relevant for flow rate	0.171 Fuß
Min. bending radius	0.081 Fuß
Temperature dependent operating pressure	-14.4 ... 145 Psi
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Food safety	to manufacturer's declaration
Ambient temperature	-31 ... 145 °F
Product weight according to length	0.48 oz/ft
Colour	silver
Shore hardness	D 52 +/-3
Materials note	Conforms to RoHS Free of copper and PTFE
Materials information for tubing	TPE-U(PU)