


# Bellows kit EADB-V1-40-S401-500

Part number: 570270

FESTO

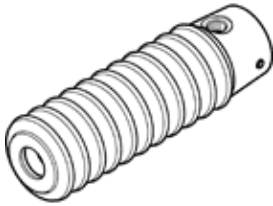

## Data sheet

Feature	Value
Outside diameter	57 mm
Size	40
Stroke range	401 ... 500 mm
Piston rod extension	135 mm
Design	Round
Assembly position	Any
Design structure	Bellows kit with ducted exhaust air
Corrosion resistance classification CRC	3
Resistance to media	Dust Chippings Oils Grease Gasolines
Protection class	IP65 to IEC 60529
Ambient temperature	-10 ... 80 °C
Moving mass	154 g
Product weight	227 g
Mounting type	slip-on With threaded pin
Pneumatic connection	G1/4
Materials note	Conforms to RoHS
Note on materials: Adapter components	Wrought Aluminium alloy Anodised
Materials information for seals	NBR
Note on materials: Bellows	NBR
Threaded stud material information	High alloy steel, non-corrosive