 



# end plate VMPAL-EPL-SD9-IP40

Part number: 570777

FESTO

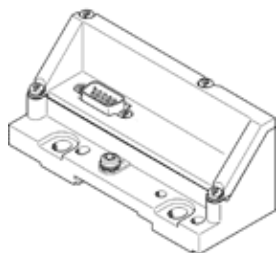

## Data sheet

Feature	Value
Width	43 mm
Length	107.3 mm
Max. number of valve positions	8
Valve terminal structure	Valve sizes can be mixed
Max. number of solenoid coils	8
Operating pressure MPa	-0.09 ... 1 MPa
Operating pressure	-0.9 ... 10 bar
Pilot pressure MPa	0.3 ... 0.8 MPa
Pilot pressure	3 ... 8 bar
Nominal operating voltage DC	24 V
Corrosion resistance classification CRC	3 - High corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Protection class	IP40
Note on degree of protection	in assembled condition
Ambient temperature	-5 ... 50 °C
Product weight	190 g
Electrical connection 1, function	Multi-pin plug
Electrical connection 1, connection type	Plug
Electrical connection 1, connection technology	Sub-D
Electrical connection 1, number of pins/wires	9
Materials note	Conforms to RoHS
Material end plate	Aluminium die cast PA-reinforced