


# Operator unit FED-400

Part number: 570864  
Product to be discontinued

FESTO

Type to be discontinued. Available until 2017. See Support Portal for alternative products.

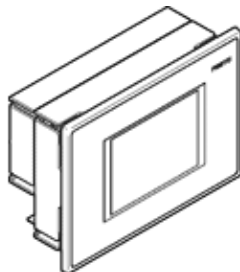

## Data sheet

Feature	Value
Depth	56 mm
Height	109 mm
Length	149 mm
Max. front panel thickness	5 mm
User memory	2 Mbyte
Real-time clock	Yes
Event lists	256
Recipe memory	32 kByte
Alarms	1,024
Real-time clock deviation	130 s / month
Number of colours	256
Display	TFT colour
Display property	Touchscreen
Display size	4,3"
Backup battery	3 V / 270 mA Lithium
Operating voltage range DC	18 ... 30 V
Display resolution	480x272 pixels
Nominal operating voltage DC	24 V
Current consumption at nominal operating voltage	0,4 A
CE mark (see declaration of conformity)	to EU directive for EMC
Storage temperature	-20 ... 70 °C
Relative air humidity	5 - 85 % non-condensing
Protection class	IP65 front, IP20 back
Ambient temperature	0 ... 50 °C
Authorisation	c UL us - Listed (OL) RCM Mark
Product weight	1,000 g
AUX interface	Sub-D 9-pin Plug socket
PC interface	RS232 Sub-D 15-pin Plug
Programming interface	9,6 - 38,4 kBd
PLC interface	RS232 Sub-D 15-pin Plug
USB interface	Yes
Ethernet interface	100 MBd
Mounting type	Front panel installation
Materials note	Conforms to RoHS
Programming software	FED Designer 6.09 or higher