


# Connecting cable NEBS-L2G5-K-2.5-LE5

Part number: 570920

FESTO

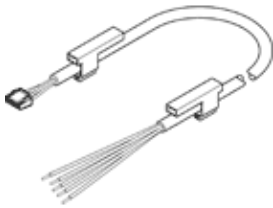

## Data sheet

Feature	Value
Cable attribute	Standard
Test conditions of cable	Bending strength according to Festo standard Test conditions on request
Operating voltage range DC	0 ... 30 V
Surge strength	0.8 kV
Acceptable current load at 40°C	1 A
Degree of contamination	2
Protection class	IP40
Ambient temperature with flexible cable installation	-5 ... 60 °C
Ambient temperature	-20 ... 60 °C
Electrical connection 1	Socket, rectangular design L2, 5-pin
Electrical connection 2	Open end, 5-wire
Cable structure	5 x 0,14 mm <sup>2</sup>
Cable diameter	4.1 mm
Cable length	2.5 m
Nominal conductor cross-section	0.14 mm <sup>2</sup>
Colour code, core insulation	blue brown Grey Black white
Cable sheath colour	Grey
Materials note	Free of copper and PTFE Conforms to RoHS
Materials information, housing	PBT
Material information, isolating sleeve	PP
Materials information, cable sheaths	PVC