


# Manifold rail VABM-L1-14G-G14-24-GR

Part number: 573499

FESTO

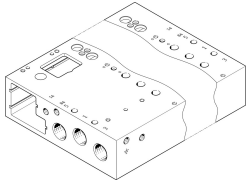

## Data sheet

Feature	Value
Grid dimension	16 mm
Mounting position	optional
Max. number of valve positions	24
Approval	c UL us - Recognized (OL)
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Storage temperature	-20 °C...60 °C
Product weight	3099 g
Pilot air port 12/14	M5
Pilot exhaust port 82/84	M5
Pneumatic connection, port 1	G1/4
Pneumatic connection, port 3	G1/4
Pneumatic connection, port 5	G1/4
Note on materials	RoHS-compliant
Material manifold rail	Wrought aluminium alloy