 



vertical pressure exhaust plate

VABF-L1-P7A13-M7

Part number: 574594

FESTO

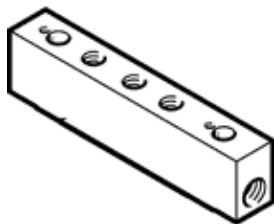

Data sheet

Feature	Value
Grid dimension	10.5 mm
Max. number of valve positions	1
Operating pressure MPa	-0.09 ... 1 MPa
Operating pressure	-0.9 ... 10 bar
Authorisation	RCM Mark c UL us - Recognized (OL)
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Max. tightening torque, valve mounting	0.45 Nm
Product weight	220 g
Pneumatic connection, port 3	M7
Pneumatic connection, port 5	M7
Materials note	Conforms to RoHS
Material plate	Wrought Aluminium alloy