


bus interface CDPX-F-CO

Part number: 575301

FESTO

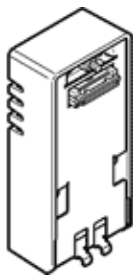

Data sheet

| Feature | Value |
|--|---|
| Depth | 24 mm |
| Height | 91 mm |
| Length | 41 mm |
| Authorisation | C-Tick c UL us - Listed (OL) |
| CE mark (see declaration of conformity) | to EU directive for EMC in accordance with EU RoHS directive |
| UKCA marking (see declaration of conformity) | To UK instructions for EMC To UK RoHS instructions |
| PWIS conformity | VDMA24364 zone III |
| Storage temperature | -20 ... 70 °C |
| Relative air humidity | 5 - 85 % non-condensing |
| Protection class | IP20 |
| Ambient temperature | 0 ... 50 °C |
| Product weight | 150 g |
| Materials note | Conforms to RoHS |
| Fieldbus interface | CANopen |
| Fieldbus interface, connection technology | Plug Sub-D 9-pin |
| Fieldbus interface, transmission rate | 9,6 kbit/s bis 1 Mbit/s |