


terminal strip NECU-L3G7-C1

Part number: 576319

FESTO

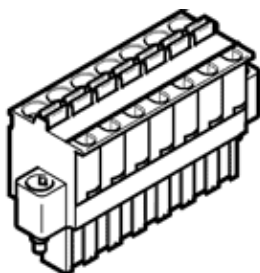

Data sheet

Feature	Value
Authorisation	c UL us - Listed (OL)
Connection frequency	100
Assembly position	Any
Product weight	12.8 g
Electrical connection	7-pin Cage clamp terminal Plug straight
Operating voltage range DC	0 ... 30 V
Acceptable current load at 40°C	12 A
Surge strength	4 kV
Terminal cross-section	0.2 ... 2.5 mm ²
Ambient temperature	-40 ... 85 °C
PWIS conformity	VDMA24364-B2-L
Materials note	Conforms to RoHS
Degree of contamination	3
Corrosion resistance classification CRC	2 - Moderate corrosion stress
Material housing	PA
Housing colour	Black
Material electrical contact	Copper alloy Galvanised