


multi-socket KDVF-32-B

Part number: 7565

FESTO

For multiple tube connector for plastic tubing ND 2, 3 and 4 mm.

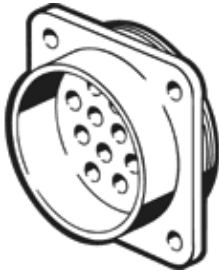

Data sheet

Feature	Value
Nominal size	4 mm
Operating pressure	-0.95 ... 16 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Medium temperature	-10 ... 60 °C
Ambient temperature	-10 ... 60 °C
Product weight	131 g
Max. number of connections	32
Pneumatic connection	PK-2 PK-3 PK-4
Colour	Grey
Materials note	Conforms to RoHS