


# control cable NEBC-S1G25-K-3.2-N-LE25

Part number: 8001373

FESTO

Connected to the motor controller; the other end comprises individual leads.

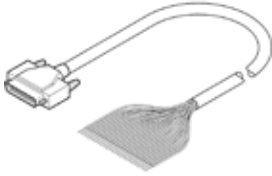

## Data sheet

Feature	Value
Electrical connection	25-pin Straight plug/open at one end Sub-D / -
Cable length	3.2 m
Cable diameter	7 mm
Cable structure	Shielded
Protection class	IP40 in assembled condition
CE mark (see declaration of conformity)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364 zone III
Materials note	Conforms to RoHS
Corrosion resistance classification CRC	0 - No corrosion stress
Cable sheath colour	Grey
Housing colour	Grey