


# handling module

## EHMY-RP-EGC-125-TB-HD- -

Part number: 8004608

FESTO

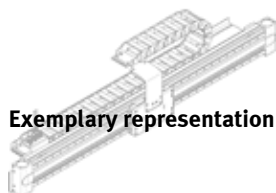

Exemplary representation

## Data sheet

Overall data sheet – Individual values depend upon your configuration.

Feature	Value
Working stroke	50 ... 2,000 mm
Required flatness of the mounting surfaces	0.1 mm/m
Assembly position	Horizontal
Design structure	Electromechanical linear module With toothed belt
Position detection	For proximity sensor
Repetition accuracy	±0,08 mm
Duty cycle	100 %
PWIS conformity	VDMA24364 zone III
Storage temperature	-20 ... 60 °C
Relative air humidity	0 - 90 %
Protection class	IP40
Ambient temperature	5 ... 45 °C
Materials note	Conforms to RoHS