


# manifold rail

## VABM-L1-18G-G38-16-M-G

Part number: 8004910

FESTO

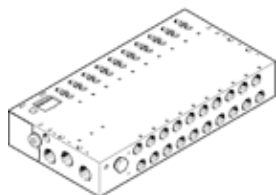

### Data sheet

Feature	Value
Grid dimension	19 mm
Assembly position	Any
Max. number of valve positions	16
Authorisation	c UL us - Recognized (OL)
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Storage temperature	-20 ... 60 °C
Product weight	3,861 g
Auxiliary pilot air port 12/14	G1/8
Pilot exhaust port 82/84	G1/8
Pneumatic connection, port 1	G3/8
Pneumatic connection, port 3	G3/8
Pneumatic connection, port 5	G3/8
Materials note	Conforms to RoHS
Material manifold	Wrought Aluminium alloy