


flow control VFFG-T-M5-12

Part number: 8025714

FESTO

This type is suitable for vacuum.

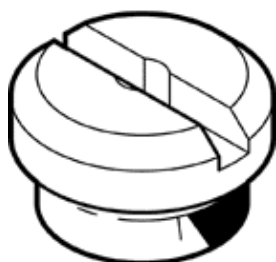

Data sheet

| Feature | Value |
|--|---|
| Valve function | Throttle function |
| Mounting type | with thread |
| Standard nominal flow rate in flow control direction | 45.4 l/min |
| Operating pressure | -0.9 ... 10 bar |
| Ambient temperature | -5 ... 60 °C |
| Nominal size | 1.2 mm |
| b value | 0.5 |
| C value | 0.16 l/sbar |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [7:4:4] |
| Note on operating and pilot medium | Lubricated operation possible (subsequently required for further operation) |
| PWIS conformity | VDMA24364-B1/B2-L |
| Storage temperature | -20 ... 60 °C |
| Product weight | 0.5 g |
| Materials note | Conforms to RoHS |
| Material hollow bolt | PA |