


supply plate

VABF-B10-25-P1-G14

Part number: 8026317

FESTO

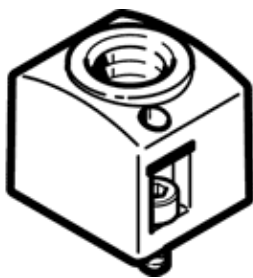

Data sheet

Feature	Value
Operating pressure MPa	-0.09 ... 1 MPa
Operating pressure	-0.9 ... 10 bar
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Max. tightening torque	3 Nm
Product weight	26 g
Mounting type	with through hole
Pneumatic connection, port 1	G1/4
Materials note	Conforms to RoHS
Material supply plate	Aluminium die cast