


# Linear gantry EXCT-15- -

Part number: 8026575

FESTO

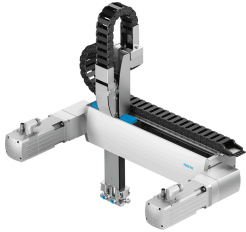

## Data sheet

Feature	Value
Size	15
Mounting position	Vertical
Design	Linear gantry
Operating pressure	-0.95 bar...8 bar
Max. acceleration	50 m/s <sup>2</sup>
Max. speed	4.8 m/s
Repetition accuracy	±0.1 mm
Duty cycle	100%
LABS (PWIS) conformity	VDMA24364 zone III
Storage temperature	-10 °C...60 °C
Relative air humidity	0 - 90%
Sound pressure level	70 dB(A)
Degree of protection	IP40
Ambient temperature	10 °C...40 °C
Max. process force in Z direction	100 N
Nominal load at max. dynamic response	1.5 kg
Type of mounting	Via mounting kit Via slot nuts
Note on materials	RoHS-compliant