 



Vertical pressure supply plate VMPA2-VSP-QS5/16

Part number: 8029491

FESTO

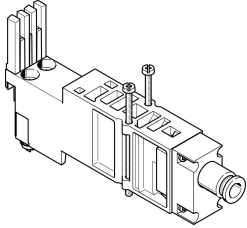

Data sheet

Feature	Value
Grid dimension	21 mm
Operating pressure	-0.09 MPa...1 MPa -0.9 bar...10 bar
Pilot pressure	0.3 MPa...0.8 MPa 3 bar...8 bar
Operating medium	Compressed air to ISO 8573-1:2010 [7:4:4]
Corrosion resistance class CRC	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-5 °C...50 °C
Product weight	85 g
Pneumatic connection, port 1	QS-5/16
Note on materials	RoHS-compliant
Material supply plate	PA-reinforced