


# sub-base VMPA2-FB-AP-2-1-RV

Part number: 8034548

FESTO

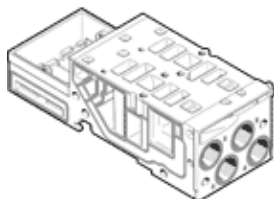

## Data sheet

Feature	Value
Width	51 mm
Length	107.3 mm
Grid dimension	21 mm
Max. number of valve positions	2
Operating pressure MPa	-0.09 ... 1 MPa
Operating pressure	-0.9 ... 10 bar
Pilot pressure MPa	0.3 ... 0.8 MPa
Pilot pressure	3 ... 8 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-5 ... 50 °C
Product weight	190 g
Materials note	Conforms to RoHS
Material of connecting plate	Aluminium die cast