 



Vertical pressure supply plate VMPA2-VSP-QS1/4

Part number: 8035442

FESTO

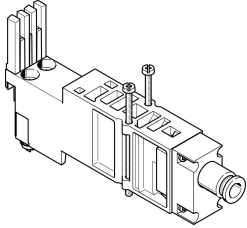

Data sheet

| Feature | Value |
|--------------------------------|---|
| Grid dimension | 21 mm |
| Operating pressure | -0.09 MPa...1 MPa -0.9 bar...10 bar |
| Pilot pressure | 0.3 MPa...0.8 MPa 3 bar...8 bar |
| Operating medium | Compressed air to ISO 8573-1:2010 [7:4:4] |
| Corrosion resistance class CRC | 1 - Low corrosion stress |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |
| Ambient temperature | -5 °C...50 °C |
| Product weight | 80 g |
| Pneumatic connection, port 1 | QS-1/4 |
| Note on materials | RoHS-compliant |
| Material supply plate | PA-reinforced |